
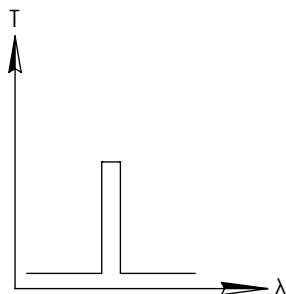
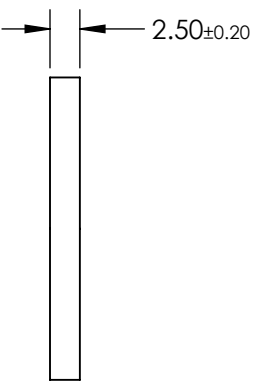
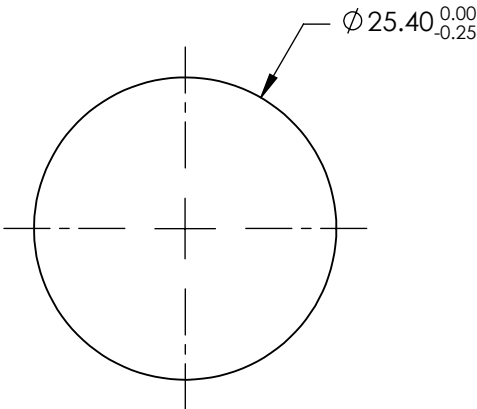


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

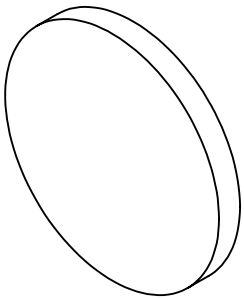


BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | VALUE |
|---------------------------------|----------------------|
| SHAPE | PLANO |
| CENTER WAVELENGTH (nm) | 390 |
| FULL WIDTH HALF MAX (FWHM) (nm) | 125 |
| SURFACE QUALITY | 60-40 |
| COATING TYPE | Uncoated |
| BEVEL | PROTECTIVE AS NEEDED |



ALL DIMS IN mm

| | | | |
|---|-------|--|--|
|  Edmund Optics® | | | |
| TITLE | | HOYA B-390 (UV-VIS) 25.4mm Dia., Colored Glass Bandpass Filter | |
| DWG NO | 48635 | SHEET 1 OF 1 | |