
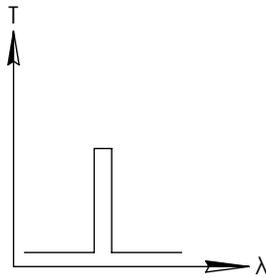
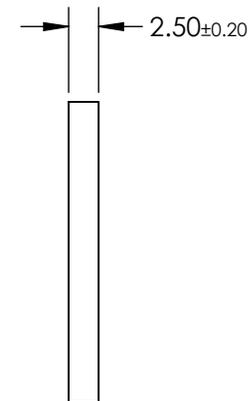
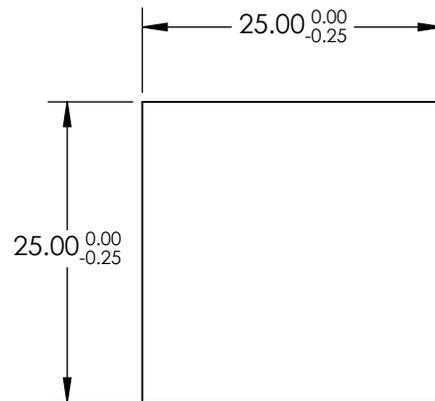


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

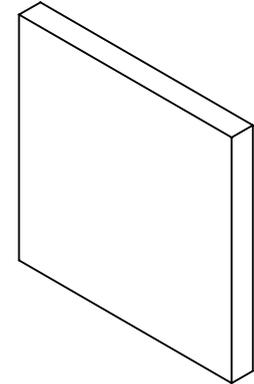


BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | VALUE |
|---------------------------------|----------------------|
| SHAPE | PLANO |
| CENTER WAVELENGTH (nm) | 550 |
| FULL WIDTH HALF MAX (FWHM) (nm) | 180 |
| SURFACE QUALITY | 80-50 |
| CAOTING TYPE | Uncoated |
| BEVEL | PROTECTIVE AS NEEDED |



THIRD ANGLE
PROJECTION

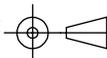

TITLE

HOYA G550 (VIS) 25mm Square, Colored
Glass Bandpass Filter

ALL DIMS IN

mm

DWG NO

34452

SHEET
1 OF 1