

NOTES:

1. SUBSTRATE MATERIAL:
BOROFLOAT®




2. COATING (APPLY ACROSS CLEAR APERTURE)

S1: R(avg) <0.5% @ 425 - 675nm
HYDROPHOBIC COATING - REPELS WATER, OIL AND
DEBRIS

S2:NONE

3. FINE GRIND SURFACE

4. ROHS COMPLIANT

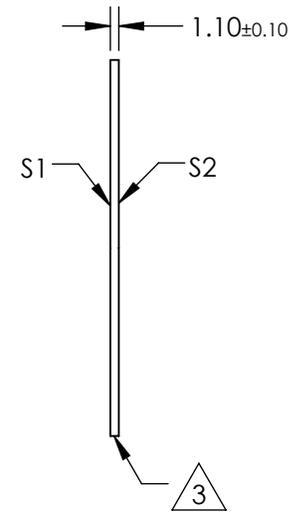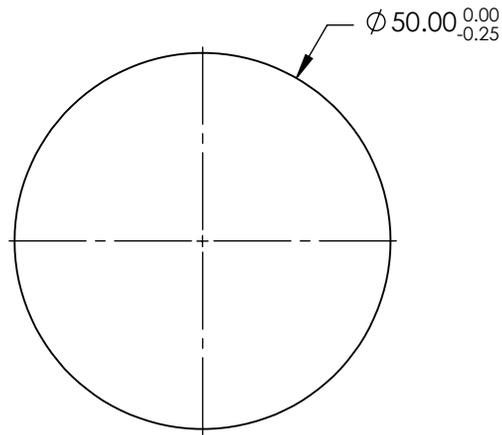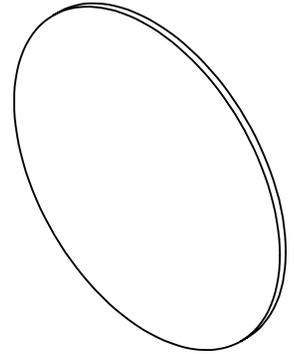

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	S1	S2
SHAPE	PLANO	PLANO
SURFACE QUALITY	80 - 50	80 - 50
CLEAR APERTURE	Ø45.00	Ø45.00
BEVEL	PROTECTIVE AS NEEDED	PROTECTIVE AS NEEDED

THIRD ANGLE PROJECTION

ALL DIMS IN mm

Edmund Optics®

TITLE

WINDOW BORO HYDRO & OLEO 50MM TS
Indoor

DWG NO

36073

SHEET
1 OF 1