
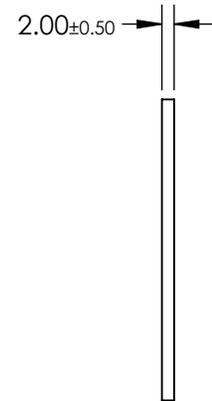
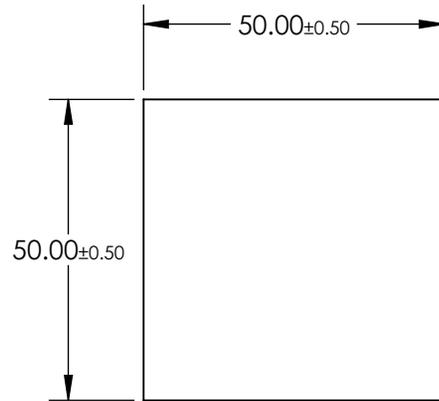
 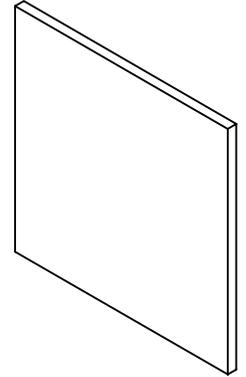


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**



SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	300
WAVELENGTH RANGE (nm)	250 - 500
BLAZE ANGLE	8.6°
RoHS	COMPLIANT

THIRD ANGLE PROJECTION 

ALL DIMS IN mm

EO® **Edmund Optics**®

TITLE	300 Grooves/mm, 50mm Sq, UV Transmission Grating Beamsplitter	
DWG NO	85296	SHEET 1 OF 1