
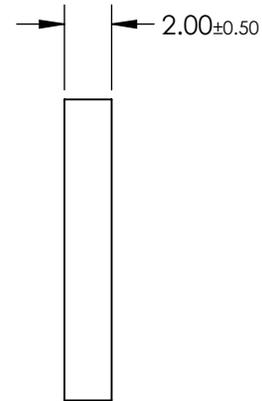
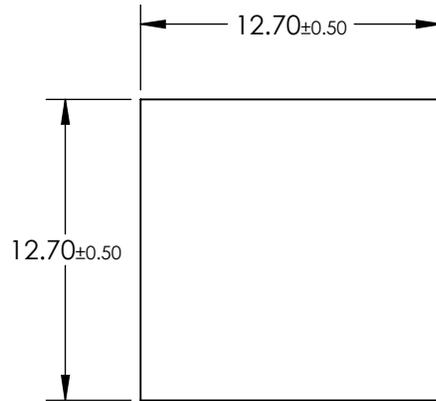


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

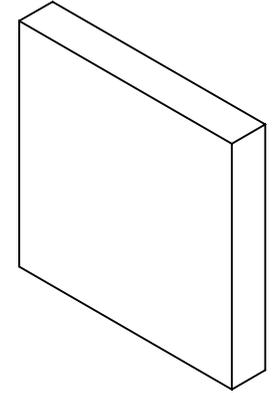

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	600
WAVELENGTH RANGE (nm)	250 - 600
BLAZE ANGLE	22.0°
RoHS	COMPLIANT

EO® **Edmund Optics**®



ALL DIMS IN

mm

TITLE

600 Grooves/mm, 12.7mm Sq, UV
Transmission Grating Beamsplitter

DWG NO

85288

SHEET
1 OF 1