


PN: RD-253-I-Y-A

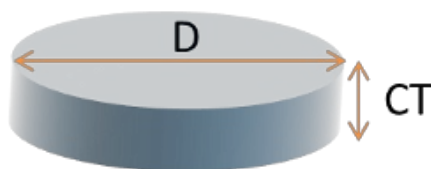

INPUT PARAMETER

Wavelength [nm]:	1064
Minimum Beam Diameter [mm]:	5
Beam Mode:	SM or MM

ELEMENT PARAMETER

Element Type:	Window
Material:	Fused Silica
Element Size [mm]:	15
Clear Aperture [mm]:	13
Thickness [mm]:	3
Coating:	AR/AR coating

OUTPUT PARAMETER

Output Shape:	Round
Full angle [deg]:	5.27
Transmission efficiency:	Close to 100%
Overall Efficiency:	~ 77%

Holo/Or can improve the performances of this item. Please send us your requirements