
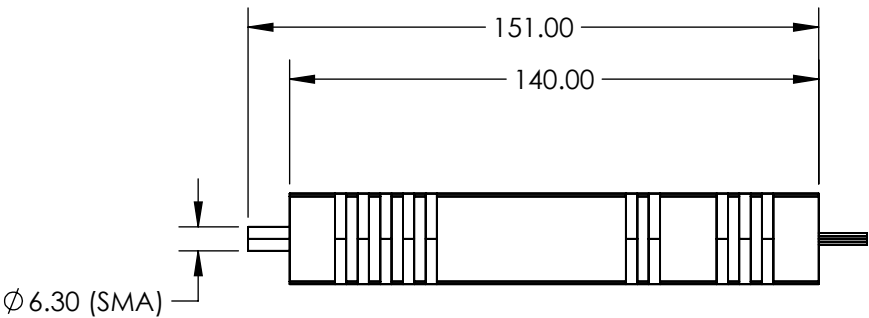
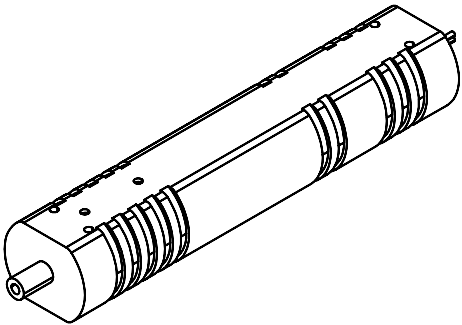


FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING

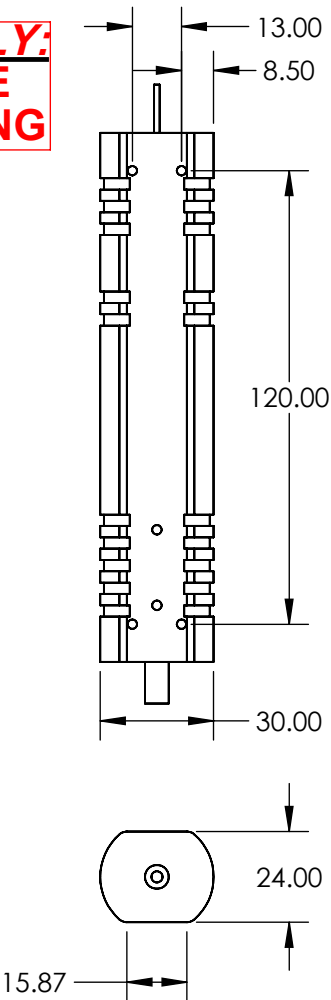

	VALUE
WAVELENGTH (nm)	450
OUTPUT POWER	100
COLOR	BLUE
LASER CLASS	CLASS IIIB
OPERATING TEMPERATURE (°C)	1 - 10
OPERATING VOLTAGE (V)	+15 to +30
SPATIAL MODE	5.0
LASER TYPE	FIBER-COUPLED
CONNECTOR	DIODE
LENGTH OF FIBER (m)	1

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

EO[®] Edmund Optics[®]



ALL DIMS IN

mm

TITLE

100mW, 450nm Fiber-Coupled Laser Module

DWG NO

19480

SHEET
1 OF 1