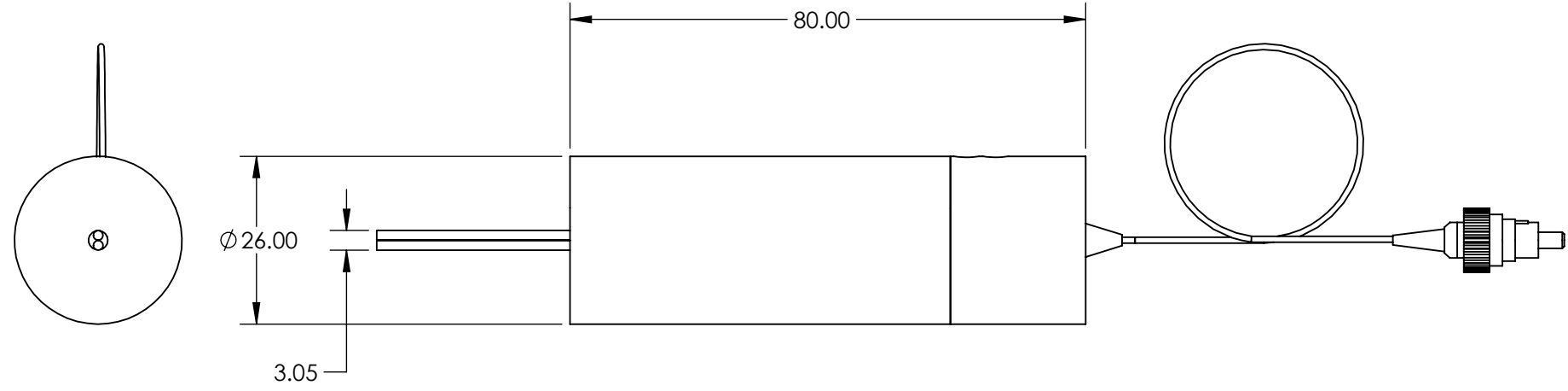
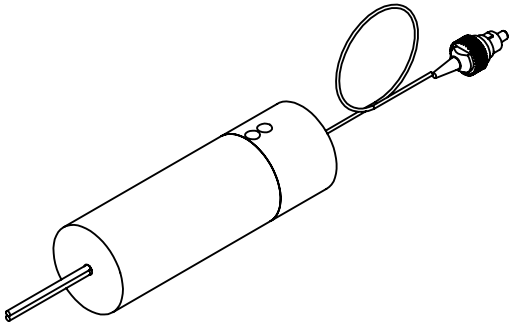


 

NOTES:

- 1. LASER CLASS:  
IIIb
- 2. OPERATING TEMPERATURE: 15 to 30 °C  
OPERATING VOLTAGE: 5V
- 3. OUTPUT POWER: 100mW
- 4. WAVELENGTH RANGE: 940±15 nm



**FOR INFORMATION ONLY:**  
**DO NOT MANUFACTURE**  
**PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

|  |    |  |       |              |
|--|----|--|-------|--------------|
| THIRD ANGLE PROJECTION  |    |  Edmund Optics® |       |              |
| TITLE  |    | 940nm 100mW Pigtailed Laser Diode  |       |              |
| ALL DIMS IN  | mm | DWG NO   | 23796 | SHEET 1 OF 1 |