


1310nm TECHSPEC Low GDD Dielectric Ultrafast Laser Mirrors

Coating Specification:

R (AVG) S & P > 99.90% @ 1310nm @ 45° AOI

R (avg) > 99.7% @ 1260 - 1360nm @ 45° AOI

Theoretical Reflection Curve

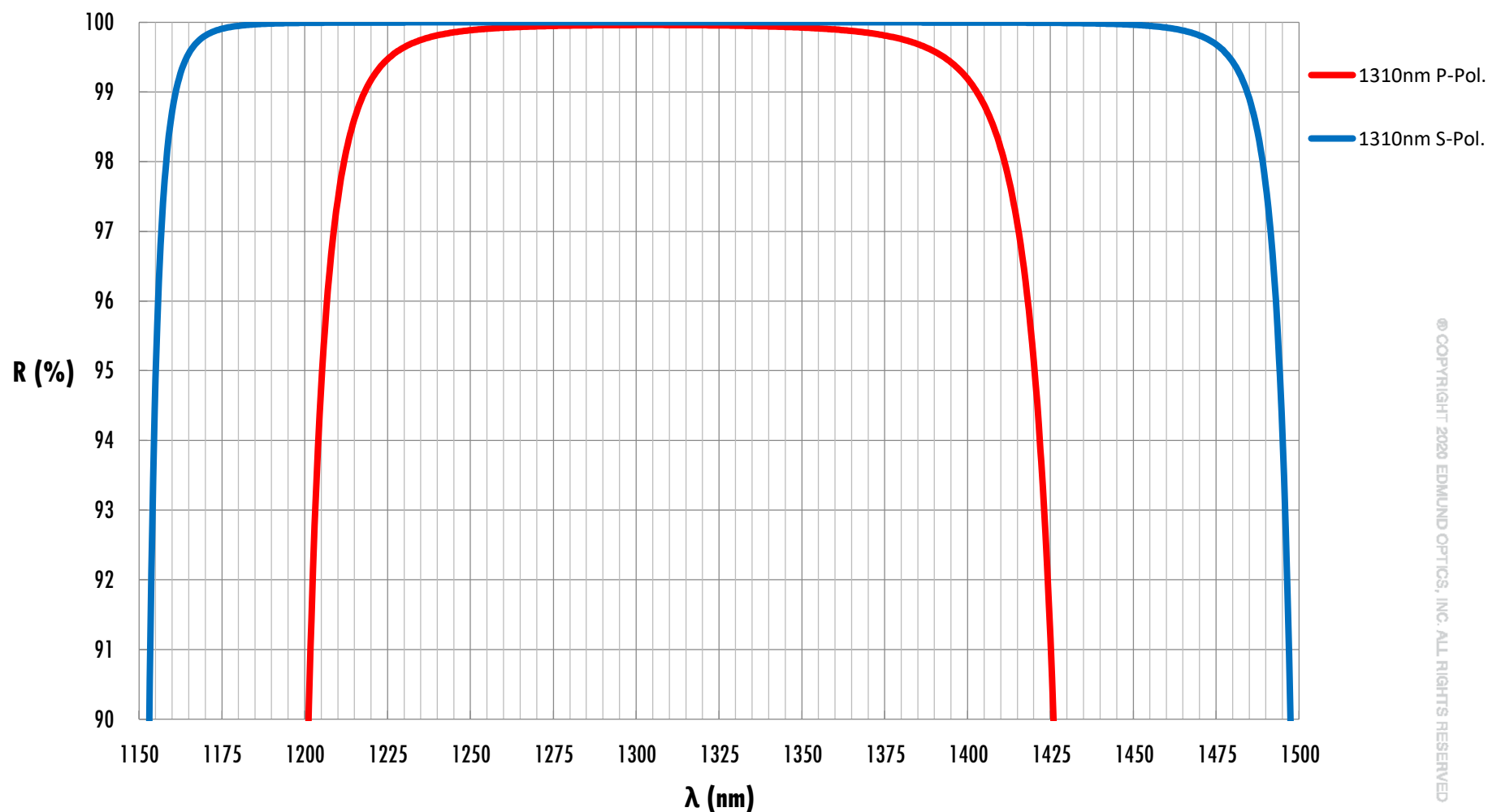

© COPYRIGHT 2020 EDMUND OPTICS, INC. ALL RIGHTS RESERVED


1310nm TECHSPEC Low GDD Dielectric Ultrafast Laser Mirrors

GDD Specification:

GDDs: $\pm 20 \text{ fs}^2$ @ 1260 - 1360nm @ 45° AOI

GDDp: $\pm 30 \text{ fs}^2$ @ 1285 - 1335 nm @ 45° AOI

Theoretical GDD Curve

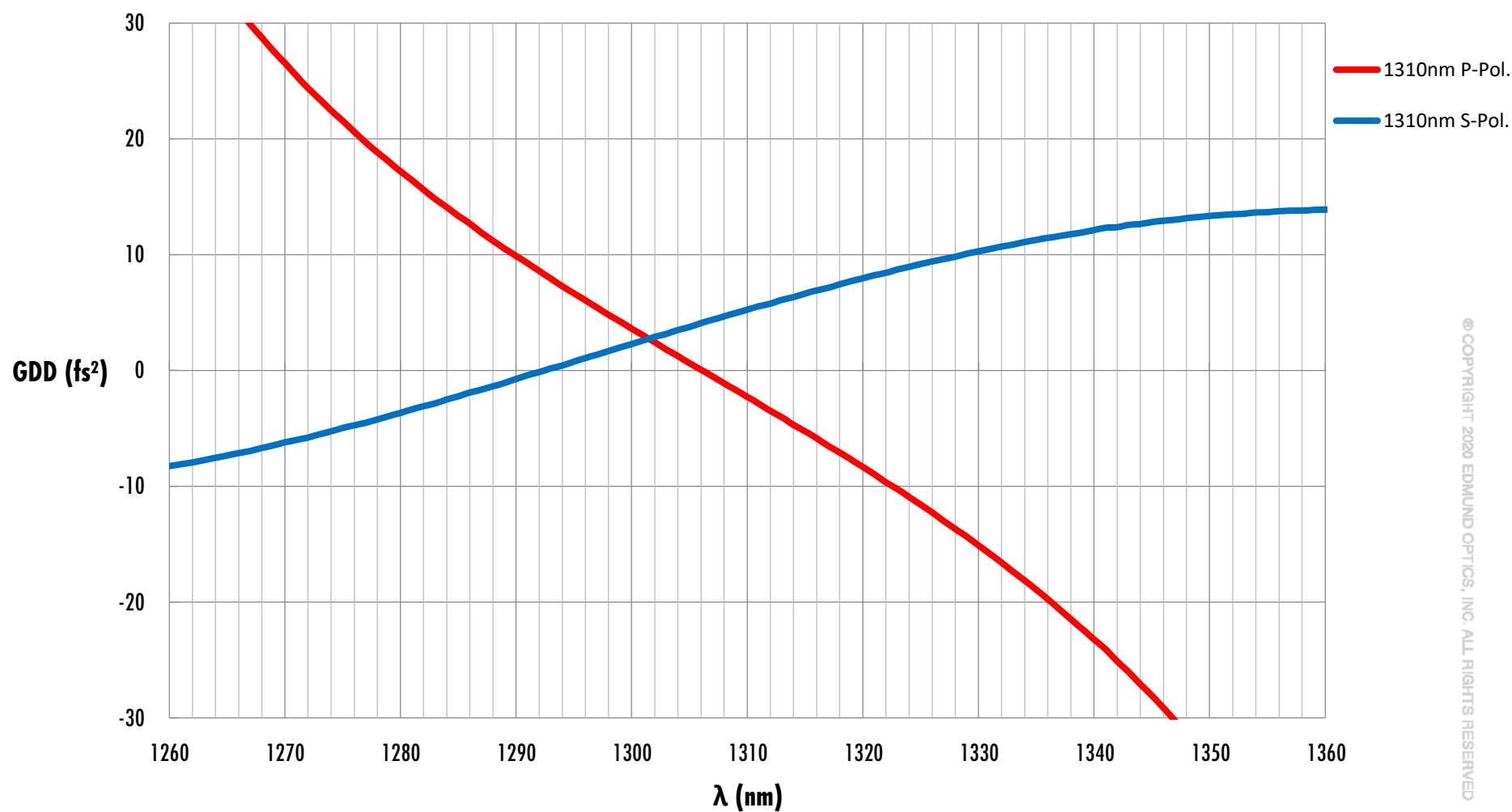

© COPYRIGHT 2020 EDMUND OPTICS, INC. ALL RIGHTS RESERVED