
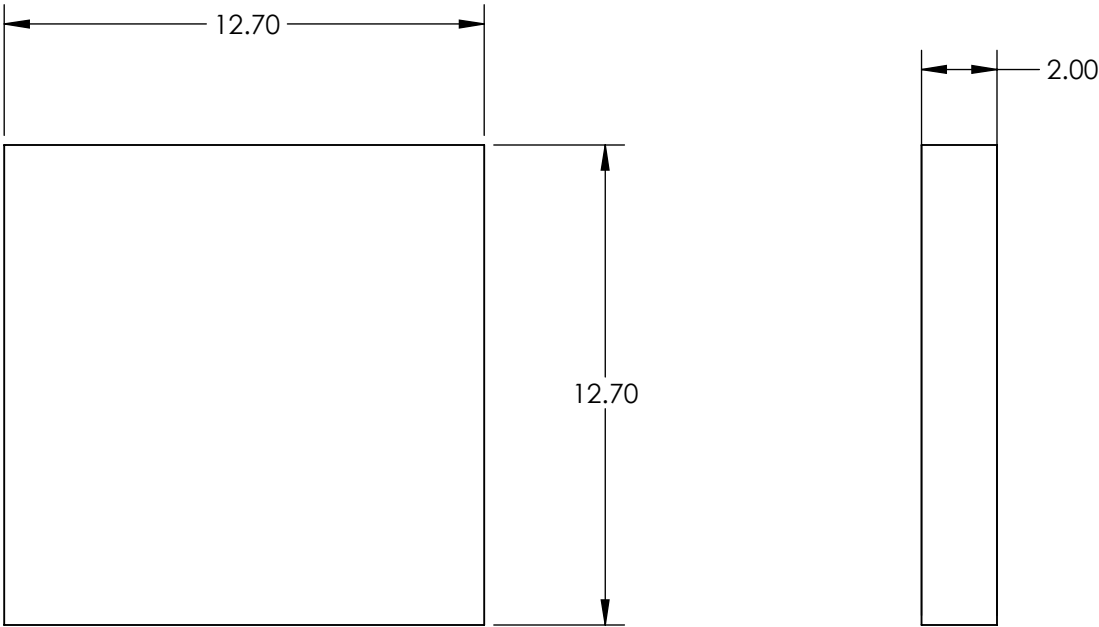
 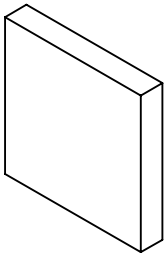



- NOTES:
- 1. GROOVE ANGLE: 26.7°
 - 2. WAVELENGTH RANGE: 190 - 400nm
 - 3. GROOVE DENSITY (grooves/mm): 1200



SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

THIRD ANGLE PROJECTION 		 Edmund Optics®		
TITLE		1200 Grooves/mm, 26.7° Groove Angle, 12.7mm Sq, DUV Transmission Grating		
ALL DIMS IN	mm	DWG NO	73799	SHEET 6 OF 12