
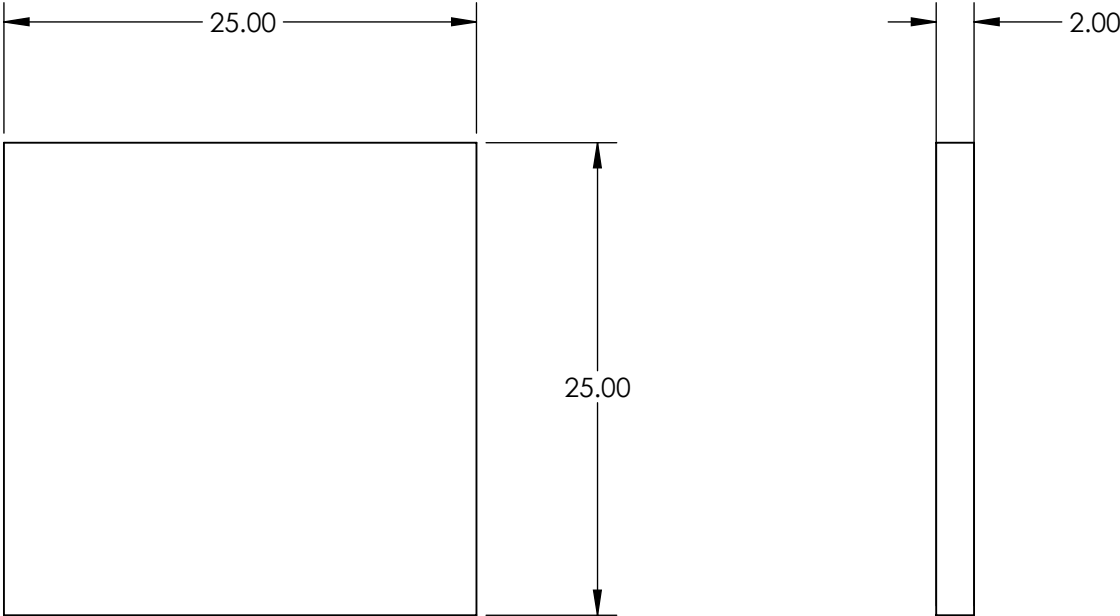


- NOTES:
- 1. GROOVE ANGLE: 8.6°
 - 2. WAVELENGTH RANGE: 190 - 400nm
 - 3. GROOVE DENSITY (grooves/mm): 300

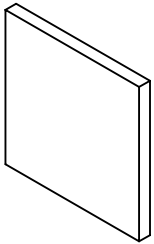

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

EO[®] Edmund Optics[®]

THIRD ANGLE PROJECTION 		TITLE	300 Grooves/mm, 8.6° Groove Angle, 25mm Sq, DUV Transmission Grating	
ALL DIMS IN	mm	DWG NO	73800	SHEET 7 OF 12