
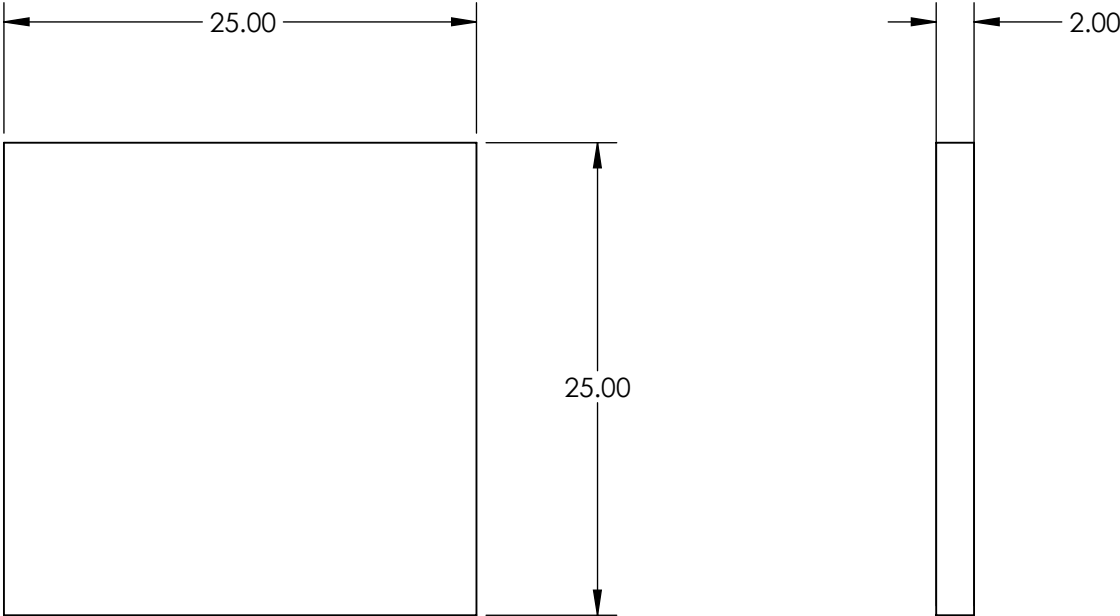


- NOTES:
- 1. GROOVE ANGLE: 19.4°
 - 2. WAVELENGTH RANGE: 190 - 400nm
 - 3. GROOVE DENSITY (grooves/mm): 830

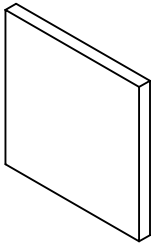

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

EO[®] Edmund Optics[®]

THIRD ANGLE PROJECTION 		TITLE	830 Grooves/mm, 19.4° Groove Angle, 25mm Sq, DUV Transmission Grating	
ALL DIMS IN	mm	DWG NO	73804	SHEET 11 OF 12