
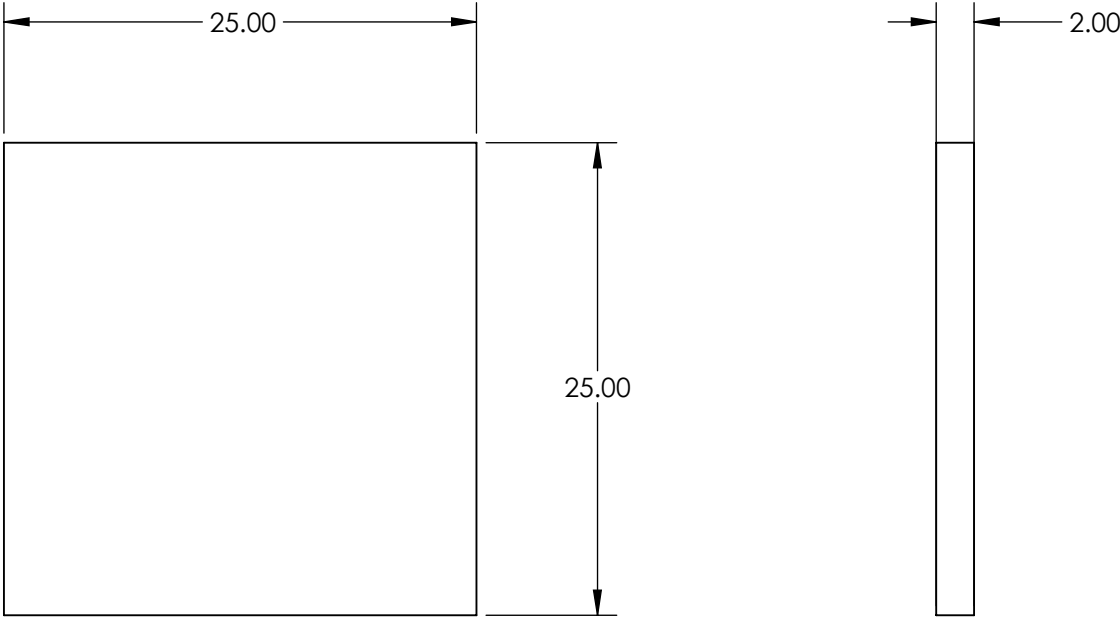


- NOTES:
- 1. GROOVE ANGLE: 26.7°
  - 2. WAVELENGTH RANGE: 190 - 400nm
  - 3. GROOVE DENSITY (grooves/mm): 1200

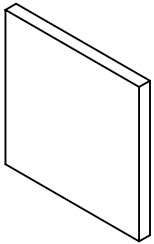

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

**EO<sup>®</sup> Edmund Optics<sup>®</sup>**

|  |    |        |   |                   |
|--|----|--------|---|-------------------|
| THIRD ANGLE PROJECTION  |    | TITLE  | 1200 Grooves/mm, 26.7° Groove Angle,<br>25mm Sq, DUV Transmission Grating |                   |
| ALL DIMS IN  | mm | DWG NO | 73805   | SHEET<br>12 OF 12 |