

[All Products](#) / [Optics | 光學產品](#) / [Prisms | 稜鏡](#) / [Image Rotation Prisms | 圖像旋轉稜鏡](#)
TECHSPEC® 阿米西屋脊稜鏡


- 光線偏離90°
- 右向旋轉的影像
- 分辨率為6角秒
- 提供未鍍膜或銀鍍膜的屋脊表面

一般規格


物理和機械特性

Dimensional Tolerance (mm):	+0/-0.1	Resolution (arcsec):	6.00
Bevel:	Protective as needed		

光學特性

Surface Quality:	60-40		
Image Orientation:	Right-Handed	Ray Deviation (°):	90
Wavelength Range (nm):	350 - 2200	Power (fringes) @ 632.8nm:	3.00
Irregularity (fringes) @ 632.8nm:	1.00		

Technical Information

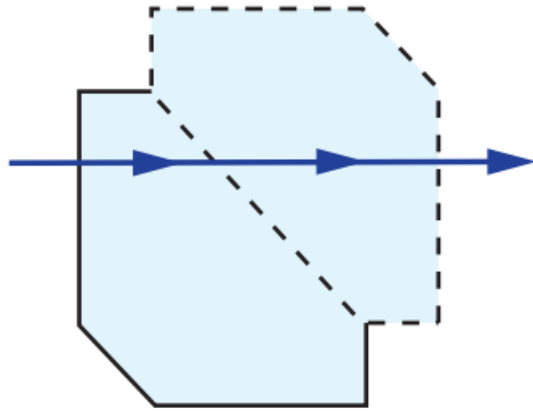

Amici Roof Prism Tunnel Diagram

產品

Coating	CA (mm)	Wavelength Range (nm)	庫存號碼	價格	Buy
Uncoated	8.00	350 - 2200	#45-662	NT\$3,263 Volume Pricing	15 庫存
Silver with protective overcoat	8.00	350 - 2200	#12-638	NT\$4,326 Volume Pricing	20+ 庫存
Uncoated	13.00	350 - 2200	#45-261	NT\$3,641 Volume Pricing	20+ 庫存
Silver with protective overcoat	13.00	350 - 2200	#12-639	NT\$4,687 Volume Pricing	4 庫存



Copyright 2023, Edmund Optics Inc., 14F., No.83, Sec. 4, Wenxin Road, Beitun District, Taichung City 406, Taiwan (R.O.C.)

電話: 1-800-363-1992 :

www.edmundoptics.com