

[All Products](#) / [Optics | 光學產品](#) / [Windows and Diffusers | 窗鏡或擴散片](#) / [UV and IR Windows | 紫外或紅外窗鏡](#)

溴化鉀 (KBr) 窗口片



- 對250nm - 26μm範圍內的光具有極佳的穿透能力
- 對機械衝擊有很高的抵抗力
- 非常適用於FTIR光譜儀
- [Sodium Chloride \(NaCl\) Windows](#) Also Available

一般規格

物理和機械特性

Bevel:	Protective as needed	Edges:	Fine Ground
Knoop Hardness (kg/mm ²):	7.00	Poisson's Ratio:	0.20
Young's Modulus (GPa):	26.8		


光學特性

Abbe Number (v _d):	33.64		
Coating:	Uncoated	Index of Refraction (n _d):	1.56
Substrate:	Potassium Bromide (KBr)	Surface Quality:	60-40
Wavelength Range (nm):	250 - 26000		

材料特性

Coefficient of Thermal Expansion CTE (10 ⁻⁶ /°C):	43		
Density (g/cm ³):	2.753	Solubility, in 100g of H ₂ O @ 273K (g):	53.48

Technical Information

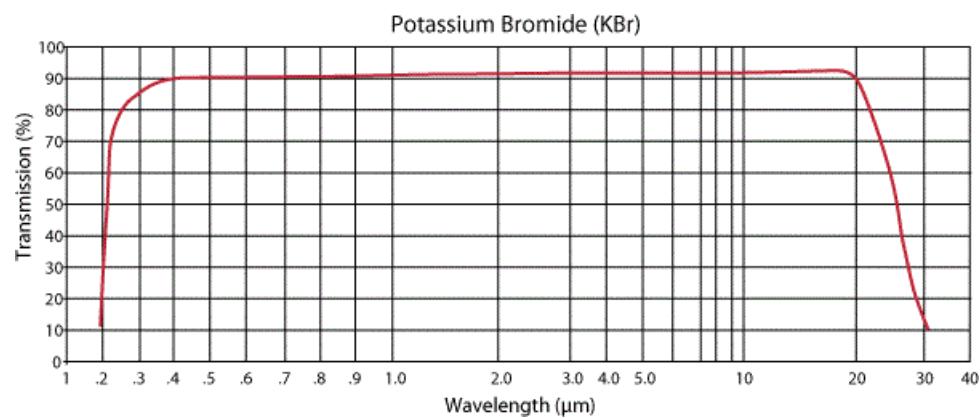

產品

Dia. (mm)	Thickness (mm)	Coating	庫存號碼	價格	Buy
13.00	1.00	Uncoated	#68-804	NT\$2,920 Volume Pricing	20+ 庫存
13.00	2.00	Uncoated	#68-805	NT\$2,920 Volume Pricing	5 庫存
20.00	2.00	Uncoated	#68-806	NT\$3,028 Volume Pricing	5 庫存
25.00	2.00	Uncoated	#68-807	NT\$3,425 Volume Pricing	聯絡我們
25.00	4.00	Uncoated	#68-808	NT\$3,425 Volume Pricing	15 庫存
25.00	5.00	Uncoated	#68-809	NT\$3,425 Volume Pricing	聯絡我們
32.00	3.00	Uncoated	#68-810	NT\$3,605 Volume Pricing	3 庫存
50.00	3.00	Uncoated	#68-811	NT\$9,950 Volume Pricing	14 庫存



Copyright 2023, Edmund Optics Inc., 14F., No.83, Sec. 4, Wenxin Road, Beitun District , Taichung City 406, Taiwan (R.O.C.)

電話: 1-800-363-1992 :

www.edmundoptics.com